

No piping needed so a Max. 85%* footprint size reduction.

Water Manifold

* Can be used with 2 types of flushing fluids.


- Rated flow: **0.5 to 4 L/min**
2 to 16 L/min
5 to 40 L/min
- Maximum **10** stations



1 Manifold

Unit type

A supply unit (supply) and a return unit (exhaust) have been integrated into a single product.

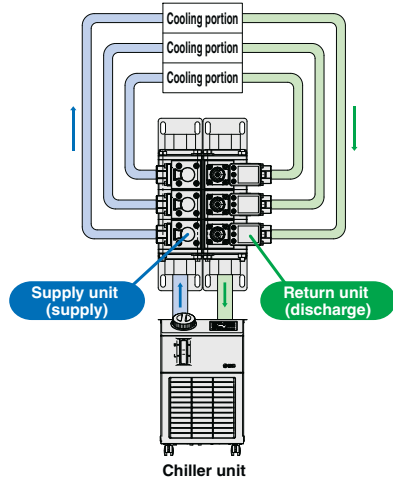


Flush type

Available for assembling a supply unit (supply) and a flush module



Remote Type Manifold

The supply unit (supply) and the return unit (discharge) can be mounted separately allowing for freedom of layout.

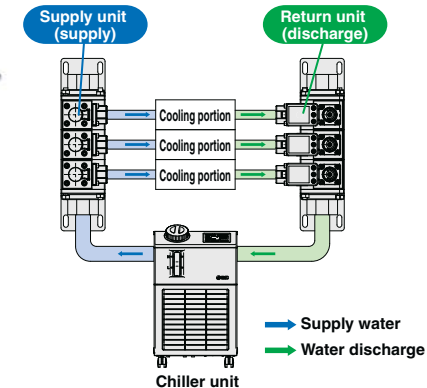

2 Types of Flushing Fluids Type

In order to avoid risks of malfunctions when performing an air purge during maintenance, the exhaust port can be switched with the general cooling port.

