


## Bulkhead Connector: KQ2E

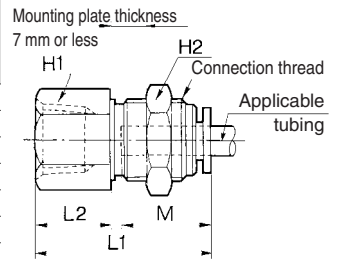


Applicable tubing O.D. (inch)	Connection thread NPT	Model	Connection thread UNF	H1 (Width across flats)	H2 (Width across flats)	L1	L2	M	Min. port size	Mounting hole	Weight (g)
1/8	1/4	<b>KQ2E01-35</b>	1/2 -20	17.46	17.46	31	15	15.5	2.5	13.5	36
5/32	1/4	<b>KQ2E03-35</b>	1/2 -20	17.46	17.46	31	15	16	3	13.5	36
3/16	1/8	<b>KQ2E05-34</b>	9/16-18	17.46	17.46	28	10	16.5	3.5	15	34
1/4	1/4	<b>KQ2E07-35</b>	9/16-18	17.46	17.46	32.5	14.5	17	4.6	15	34
5/16	3/8	<b>KQ2E09-36</b>	3/4 -16	22.23	22.23	35	15	18.5	6	20	52
1/2	3/8	<b>KQ2E11-36</b>	7/8 -14	25.4	25.4	37	14.5	21	7	23	96
	1/2	<b>KQ2E13-37</b>	1-12	28.6	28.6	37	14	22	9.6	26	125
						41.5	18				128



## Nipple: KQ2N




Applicable fitting $\phi D$	Model	L	M	$\phi d$	Weight (g)
1/8	<b>KQ2N01-99</b>	36	15.5	2.2	0.2
3/16	<b>KQ2N05-99</b>	38	16.5	3.5	0.4
1/4	<b>KQ2N07-99</b>	39	17	4.6	1
3/8	<b>KQ2N11-99</b>	49	21	7.5	10
1/2	<b>KQ2N13-99</b>	51	22	10	15

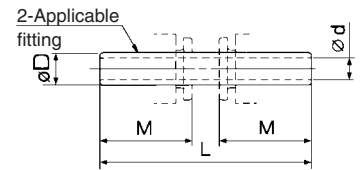

## Reducer Nipple: KQ2N




Applicable tubing O.D. (inch)		Model	L	M1	M2	$\phi d$	Weight (g)
(a)	(b)						
1/8	5/32	<b>KQ2N01-03</b>	36.5	16	15.5	2.2	0.2
	3/16	<b>KQ2N01-05</b>	37	16.5			0.4
5/32	3/16	<b>KQ2N03-05</b>	37.5	16.5	16	2.5	0.4
	1/4	<b>KQ2N03-07</b>	38	17			0.6
3/16	1/4	<b>KQ2N05-07</b>	38.5	17	16.5	3.5	0.6
	5/16	<b>KQ2N05-09</b>	41	18.5			1
1/4	5/16	<b>KQ2N07-09</b>	41.5	18.5	17	4.6	1
	3/8	<b>KQ2N07-11</b>	45	21			1
5/16	3/8	<b>KQ2N09-11</b>	46.5	21	18.5	6	11
	1/2	<b>KQ2N09-13</b>	47.5	22			22
3/8	1/2	<b>KQ2N11-13</b>	50	22	21	7	24

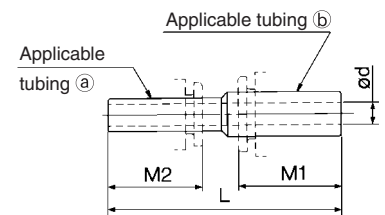

## Tube Cap: KQ2C



Applicable tubing O.D. (inch)	Model	$\phi D1$	L	M	Weight (g)
5/32	<b>KQ2C03-00</b>	10.4	17	16	1
1/4	<b>KQ2C07-00</b>	13.2	18	17	2
5/16	<b>KQ2C09-00</b>	15.2	20.5	18.5	3
3/8	<b>KQ2C11-00</b>	17.9	22.5	21	6

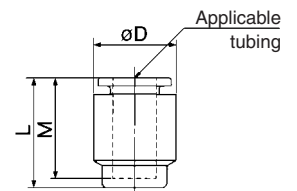

## Plug: KQ2P, KQP



Applicable fitting size $\phi d$ (inch)	Model <sup>Note)</sup>		$\phi D$	L	A	Weight (g)
1/8	<b>KQ2P-01</b>	<b>KQP-01</b>	5	31.5	16	1
5/32	<b>KQ2P-03</b>	<b>KQP-03</b>	6	32	16	1
3/16	<b>KQ2P-05</b>	<b>KQP-05</b>	6.8	34	17.5	1
1/4	<b>KQ2P-07</b>	<b>KQP-07</b>	8.5	35	18	1
5/16	<b>KQ2P-09</b>	<b>KQP-09</b>	10	39	20.5	2
3/8	<b>KQ2P-11</b>	<b>KQP-11</b>	11.5	43	22	3.5
1/2	<b>KQ2P-13</b>	<b>KQP-13</b>	15	46	24	5

