

# Related Products VR3100

## Pneumatic Indicator

Indicates the presence of pneumatic pressure. It is equivalent to the pilot lamp of an electrical system.




Symbol



### Model/Specifications


	VR3100-01R	VR3100-01G	VR3100-01O
Operating pressure	0.1 to 0.8MPa		
Ambient and fluid temp.	-5 to 60°C (No freezing)		
Frequency	100 c.p.m or less		
Color of indicator	Red	Green	Orange
Port size (Nominal size)	Rc(PT) 1/8 (6A)		
Weight	40g		

### Construction/Component Parts

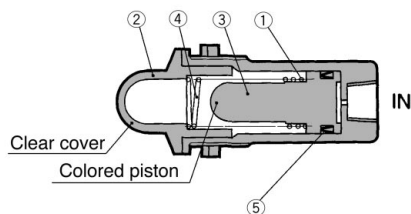

No.	Description	Material	Notes
①	Body	Aluminum alloy	
②	Indicator window	Acrylic	
③	Piston	Polyacetal	
④	Spring	Stainless steel	
⑤	Packing	NBR	

### Dimensions

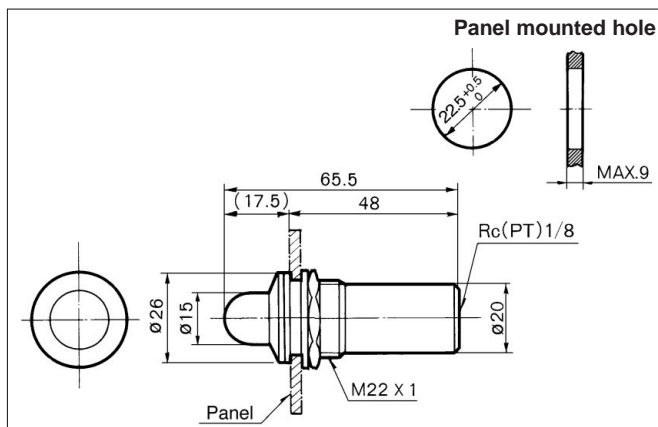

# Related Products VR3110

## Miniature Pneumatic Indicator

This is an ultra-compact air indicator light to monitor the presence of air pressure. It is equivalent to the pilot lamp of an electrical system.




Symbol



### Model/Specifications

	VR3110-01R	VR3110-01G
Color of indicator	Red	Green
Operation	Piston style	
Operating pressure	0.15 to 1.0MPa	
Ambient and fluid temp.	-5 to 60°C (No freezing)	
Frequency	300 c.p.m or less	
Port size (Nominal size)	R(PT) 1/8 (6A)	
Weight	6g	

### Construction/Component Parts

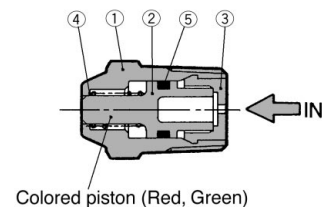

No.	Description	Material	Notes
①	Body	Brass	
②	Piston A	Polyacetal	
③	Plug	Polyethelene	
④	Spring	Stainless steel	
⑤	O ring	NBR	

### Dimensions

