

# Series ZPT/ZPR Replacement Parts

## Pad, Individual Unit

### How to Order

**ZP 10 F GN**

Pad diameter (mm)

10	ø10
13	ø13
16	ø16
20	ø20
25	ø25
32	ø32
40	ø40
50	ø50

Material

N	NBR
S	Silicon rubber
U	Urethane rubber
F	Fluoro rubber
GN <sup>+</sup>	Conductive NBR
GS <sup>+</sup>	Conductive silicon rubber

\* ø20 and larger are manufactured upon a receipt of order.

Pad type

F	Ball joint type
---	-----------------

## Lock Ring, Individual Unit


### How to Order

**ZPL F**

For ball joint type (ø40, ø50)

## Mounting Nut


### Dimensions

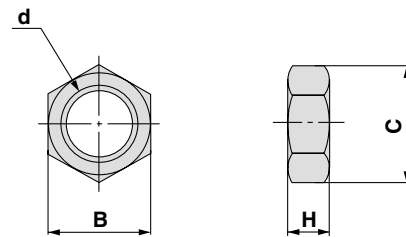


Note) Pads are exclusively ball joint type and are not interchangeable with other pads.

## Dimensions

### Ball joint type: ø10 to 32

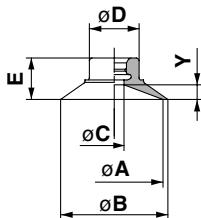

### Ball joint type: ø40, ø50

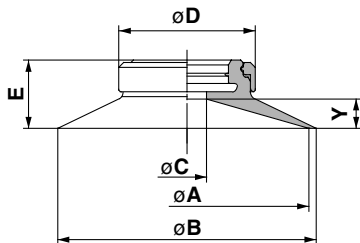

(mm)

Model	A	B	C	D	E	Y
ZP10F□□	10	12	3	8.2	6.5	1.5
ZP13F□□	13	15			7	2
ZP16F□□	16	18			8.5	3
ZP20F□□	20	22	4	10.2	9	5
ZP25F□□	25	28			13	
ZP32F□□	32	35	10	28	14	6
ZP40F□□	40	43			8	
ZP50F□□	50	53				

Model	d	H	B	C
SNJ-015A	M10 x 1	3	14	16.2
SN-015A	M14 x 1	5	19	21.9
SNJ-010A	M8 x 1	3	12	13.9

ZX

ZR

ZM

ZH

ZU

ZL

ZY

ZQ

ZF

ZP

ZCU

AMJ

Misc.